


COMPONENTS	COLOR
FC CONNECTOR	METALLIC
FC CONNECTOR	METALLIC
OFNR RATED MULTI-MODE CABLE	ORANGE

Standard Lengths	
-1	1 meter
-2	2 meters
-3	3 meters
-5	5 meters
-XXX	Custom Length in meters

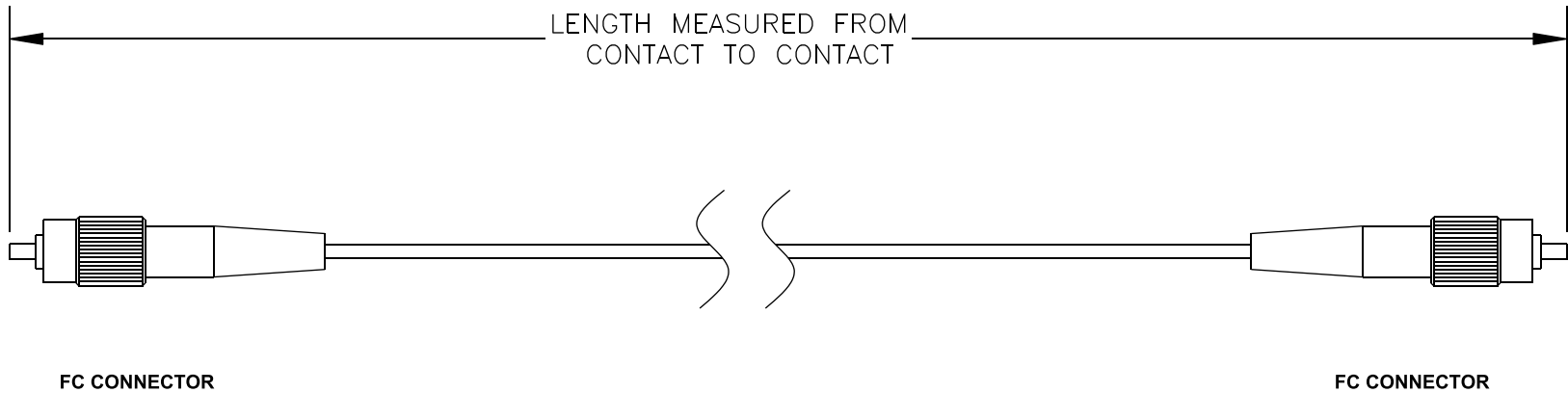

SPECIFICATIONS

POLISH: PHYSICAL CONTACT

FIBER TYPE: 62.5/125 MICRONS



PASTERNAK ENTERPRISES, INC.

P.O BOX 16759, IRVINE, CA 92623
PHONE (949) 261-1920 FAX (949) 261-7451

WEB ADDRESS: www.pasternack.com
E-MAIL ADDRESS: sales@pasternack.com

COAXIAL & FIBER OPTICS

DWG TITLE

PE300013-XX

DES.

CABLE ASSEMBLY, FC TO FC SIMPLEX,
MULTI MODE

REV. A

FSCM NO. 53919

CAD FILE

022908

SCALE N/A

SIZE A

147

NOTES:

1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN METERS.
4. LENGTH TOLERANCE IS -0/+0.153 METERS