


COMPONENTS	COLOR
LC CONNECTOR	BLUE
LC CONNECTOR	BLUE
OFNR RATED SINGLE-MODE CABLE	YELLOW

Standard Lengths	
-1	1 meter
-2	2 meters
-3	3 meters
-5	5 meters
-10	10 meters
-15	15 meters
-XXX	Custom Length in meters

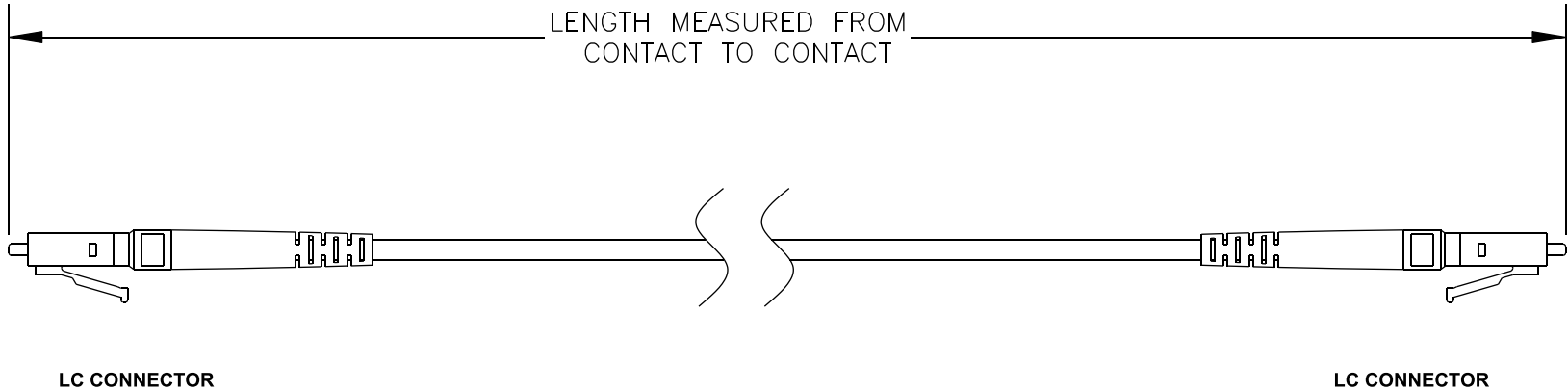

SPECIFICATIONS

POLISH: ULTRA PHYSICAL CONTACT
FIBER TYPE: 8.3/125 MICRONS



PASTERNAK ENTERPRISES, INC.
P.O BOX 16759, IRVINE, CA 92623
PHONE (949) 261-1920 FAX (949) 261-7451

WEB ADDRESS: www.pasternack.com
E-MAIL ADDRESS: sales@pasternack.com
COAXIAL & FIBER OPTICS

DWG TITLE		DES.		
PE300014-XX		CABLE ASSEMBLY, LC TO LC SIMPLEX, SINGLE MODE (9/125)		
REV. B	FSCM NO. 53919	CAD FILE 102908	SCALE N/A	SIZE A 127

NOTES:
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN METERS.
4. LENGTH TOLERANCE IS -0/+1.53 METERS