


| COMPONENTS | COLOR |
|------------------------------|--------------|
| SC CONNECTOR | BLUE & WHITE |
| LC CONNECTOR | BLUE |
| OFNR RATED SINGLE-MODE CABLE | YELLOW |
| | |

| Standard Lengths | |
|------------------|-------------------------|
| -1 | 1 meter |
| -2 | 2 meters |
| -3 | 3 meters |
| -5 | 5 meters |
| -10 | 10 meters |
| -15 | 15 meters |
| -XXX | Custom Length in meters |

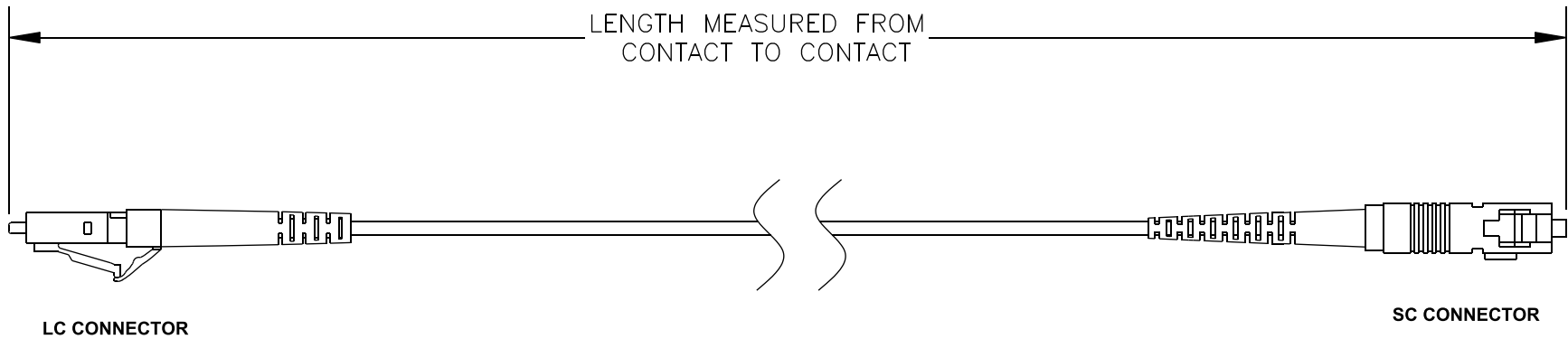

SPECIFICATIONS

POLISH: ULTRA PHYSICAL CONTACT
FIBER TYPE: 8.3/125 MICRONS



PASTERNAK ENTERPRISES, INC.

P.O BOX 16759, IRVINE, CA 92623
PHONE (949) 261-1920 FAX (949) 261-7451

WEB ADDRESS: www.pasternack.com
E-MAIL ADDRESS: sales@pasternack.com

COAXIAL & FIBER OPTICS

DWG TITLE

PE300026-XX

DES.

CABLE ASSEMBLY, SC TO LC, SIMPLEX,
SINGLE MODE (9/125)

REV. B

FSCM NO. 53919

CAD FILE 102908

SCALE N/A

SIZE A

127

NOTES:

1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN METERS.
4. LENGTH TOLERANCE IS -0/+0.153 METERS