
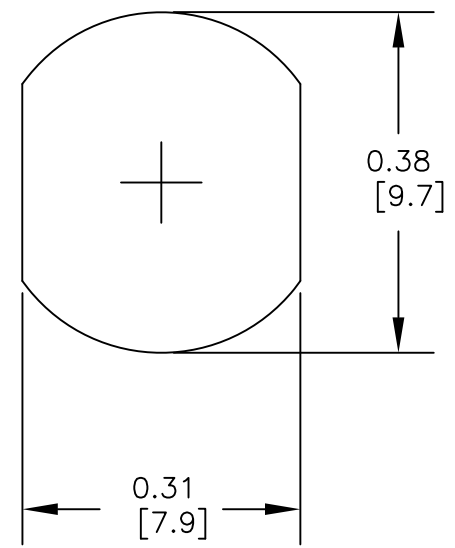


MATERIALS

SLEEVE	CERAMIC
HOUSING	METAL

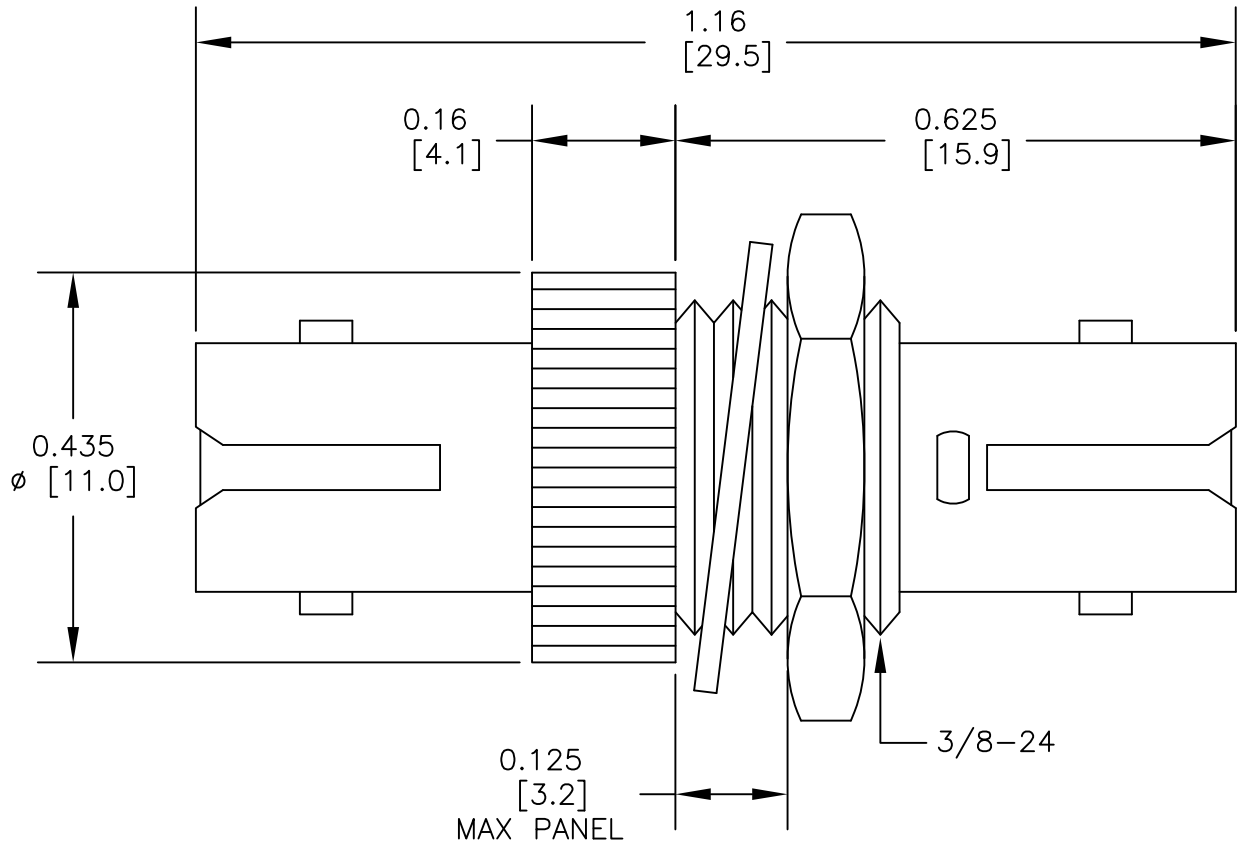

MOUNTING HOLE

SPECIFICATIONS

Single Mode
 PC Polish
 Attenuation Value: 15dB \pm 10% Typical, \pm 15% Maximum
 Operating Wavelength: 1300/1550 nm
 Insertion Loss: < 0.3dB Typical, 1dB Maximum
 Return Loss: 40 dB Minimum, > 50dB Typical
 Operating Temperature: - 40°C to + 75°C



Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623

Phone: (949) 261-1920 | Fax: (949) 261-7451

Website: www.pasternack.com | E-Mail: sales@pasternack.com

DWG TITLE

PE700003-15

DES. ST BULKHEAD ATTENUATOR, SINGLE MODE

REV. C	FSCM NO. 53919	CAD FILE 071513	SCALE N/A	SIZE A	2233
--------	----------------	-----------------	-----------	--------	------

NOTES:

1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN INCHES [mm].