



Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA

Phase Shifters and Trimmers Technical Data Sheet

PE8244

Electrical Specifications

Description	Minimum	Typical	Maximum	Units
Frequency Range	DC		4.3	GHz
Impedance		50		Ohms
Phase Adjustment	0		60	Deg/GHz
Input VSWR			1.5:1	
Output VSWR			1.5:1	
Insertion Loss			0.5	dB
Insertion Phase		320		Degrees
Group Delay			170	ps
Input Power, CW			100	Watts
Input Power, Peak			3	kWatts

Electrical Specification Notes:
Insertion Phase min. setting @ 1.0 GHz

Mechanical Specifications

Size

Length	6.9 in [175.26 mm]
Width/Diameter	2 in [50.8 mm]
Height	1 in [25.4 mm]
Weight	1.1062 lbs [501.76 g]
Finish	GY
Body Material and Plating	Aluminum

Configuration

Package Style	Connectorized
Input Connector	SMA Female
Output Connector	SMA Female

Environmental Specifications

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA PE8244](#)



Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA

Phase Shifters and Trimmers Technical Data Sheet

PE8244


Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99.4% availability and are part of the broadest selection in the industry.

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA PE8244](https://www.pasternack.com/adjustable-phase-shifter-4-ghz-sma-60-deg-per-ghz-pe8244-p.aspx)

URL: <https://www.pasternack.com/adjustable-phase-shifter-4-ghz-sma-60-deg-per-ghz-pe8244-p.aspx>

PE8244 CAD Drawing

Adjustable Phase Shifter, DC to 4.3 GHz, With an Adjustable Phase of 60 Deg. Per GHz and SMA

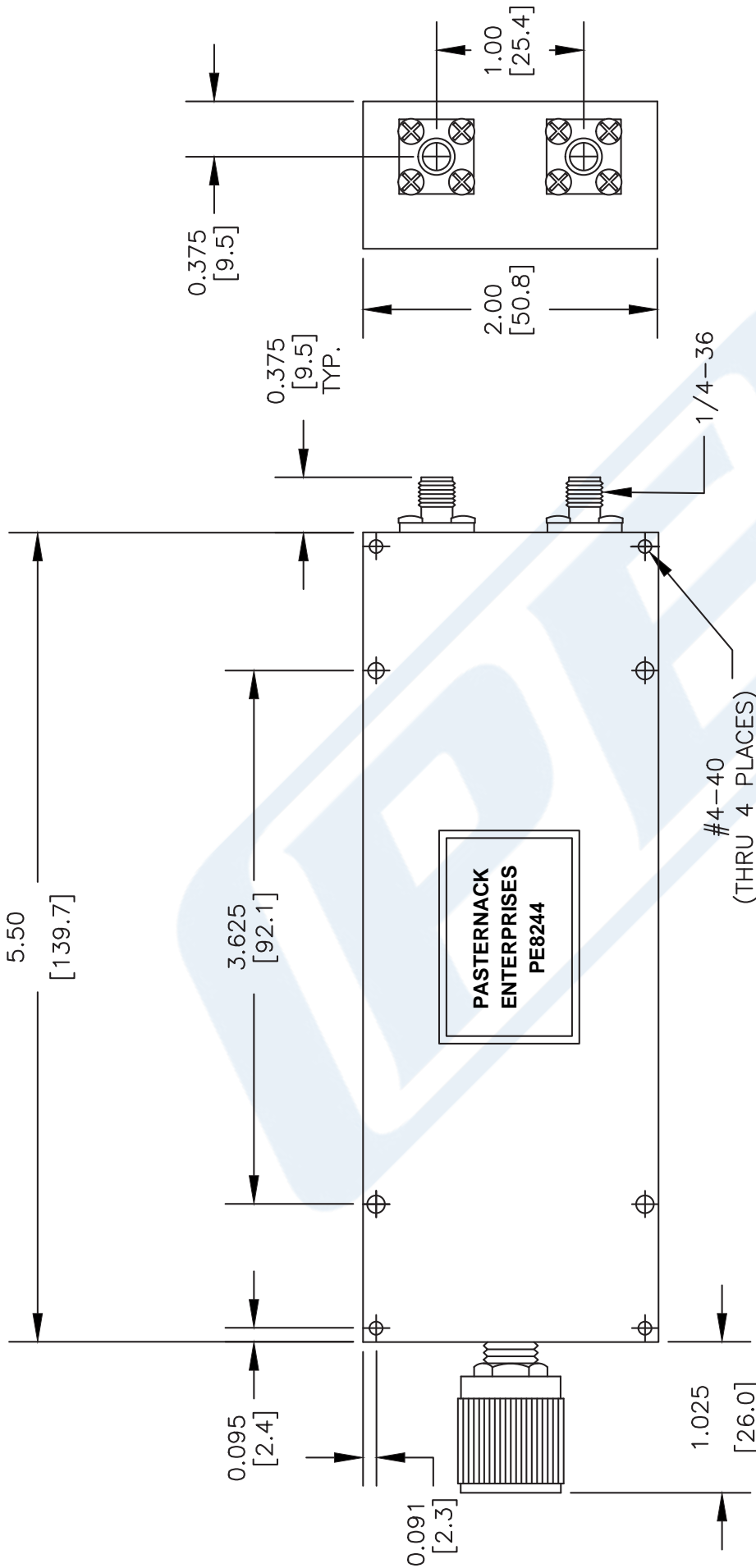

DWG TITLE

PE8244

NOTES:
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES [mm].

FSCM NO. 53919

CAD FILE 090909

SCALE N/A

SIZE A

XXXX

PE PASTERNAK®
 Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623
 Phone: (949) 261-1920 | Fax: (949) 261-7451
 Website: www.pasternack.com | E-Mail: sales@pasternack.com