



COMPONENTS	COLOR
ST MULTI MODE CONNECTOR	METALLIC
LC SINGLE MODE CONNECTOR	BLUE
LC MULTI MODE CONNECTOR	BEIGE
OFNR RATED SINGLE MODE CABLE	YELLOW
OFNR RATED MULTI MODE CABLE	ORANGE

Standard Lengths	
-1	1 meter
-2	2 meters
-3	3 meters
-5	5 meters
-10	10 meters
-15	15 meters
-XXX	Custom Length in meters

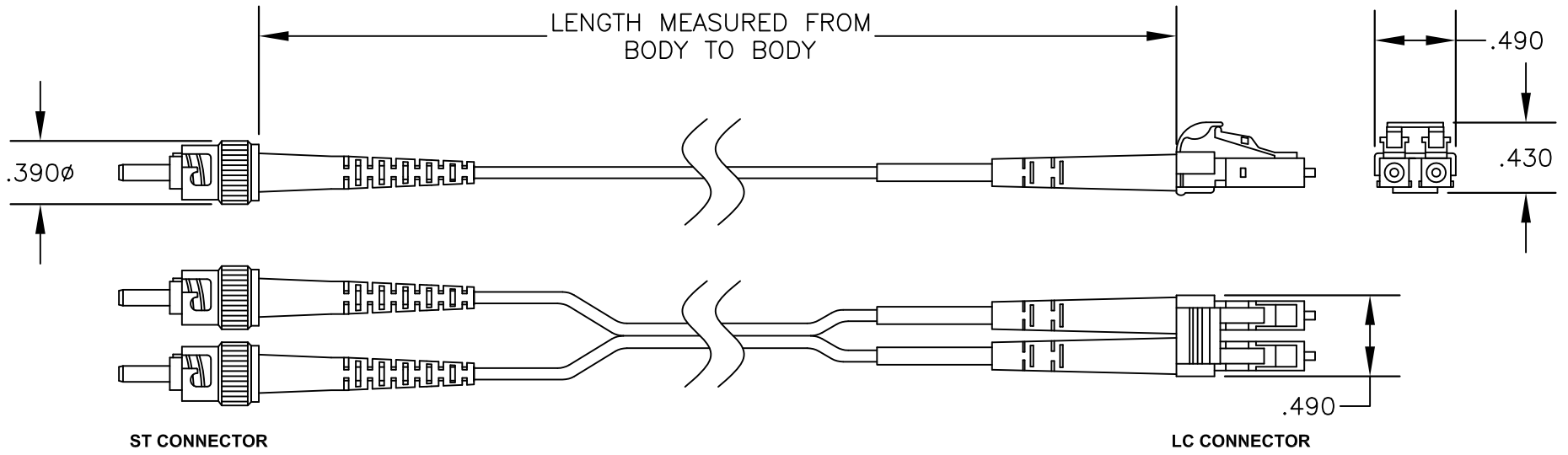

SPECIFICATIONS

POLISH: PHYSICAL CONTACT
 FIBER TYPE: 50/125 MICRONS



PASTERNAK ENTERPRISES, INC.
 P.O BOX 16759, IRVINE, CA 92623
 PHONE (949) 261-1920 FAX (949) 261-7451
 WEB ADDRESS: www.pasternack.com
 E-MAIL ADDRESS: sales@pasternack.com
COAXIAL & FIBER OPTICS

ESTABLISHED 1972

DWG TITLE	PE300531-XX		DES.	CABLE ASSEMBLY, ST SINGLE MODE DUPLEX TO LC SINGLE MODE & MULTI MODE DUPLEX, MODE CONDITIONING			
REV. -	FSCM NO. 53919	CAD FILE	030110	SCALE	N/A	SIZE	A 147

NOTES:
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN METERS.
 4. LENGTH TOLERANCE IS -0/+ .153 METERS