



COMPONENTS	IMPEDANCE
BNC FEMALE	75 OHM
BNC FEMALE	75 OHM
RG216/U	75 OHM

Standard Lengths	
-12	12"
-24	24"
-36	36"
-48	48"
-60	60"
-XXX	Custom Length in inches

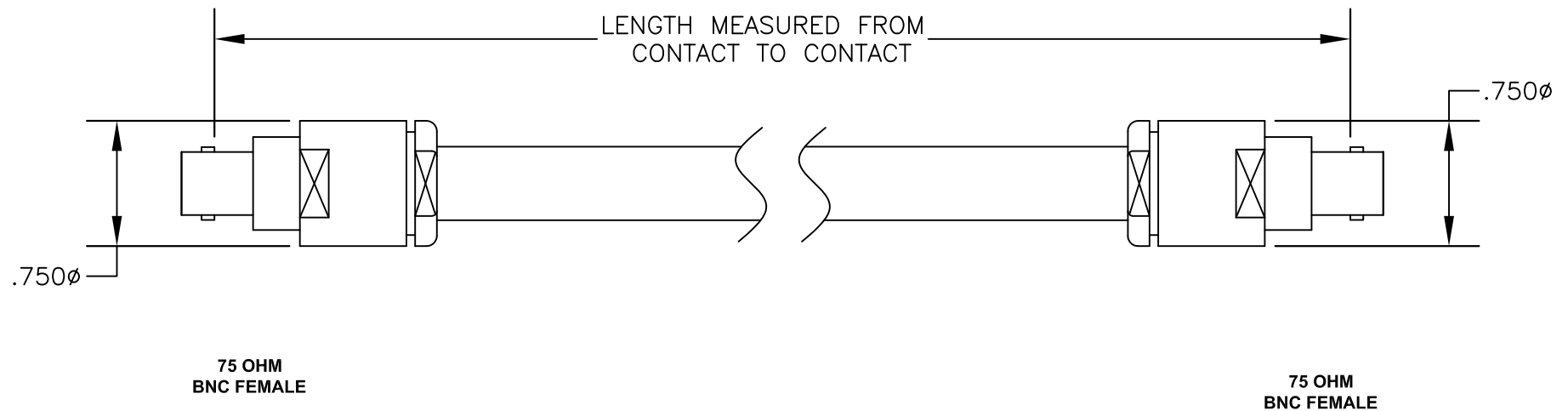



PASTERNAK ENTERPRISES®
ESTABLISHED 1972

PASTERNAK ENTERPRISES, INC.
P.O BOX 16759, IRVINE, CA 92623
PHONE (949) 261-1920 FAX (949) 261-7451

WEB ADDRESS: www.pasternack.com
E-MAIL ADDRESS: sales@pasternack.com

COAXIAL & FIBER OPTICS

DWG TITLE PE33458-XX	DES. CABLE ASSEMBLY, RG216/U, 75 OHM BNC FEMALE TO 75 OHM BNC FEMALE (LEAD FREE)
REV. - FSCM NO. 53919	CAD FILE 011708 SCALE N/A SIZE A 127

- NOTES:**
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES.
 4. LENGTH TOLERANCE IS ± 1.5% OR 10mm, WHICHEVER IS GREATER.