



## 3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN

### RF Terminations Technical Data Sheet

**PE410-06403-033**

#### Applications

- TRB PLUG

#### Electrical Specifications

Description	Minimum	Typical	Maximum	Units
Frequency Range	DC		500	MHz
Impedance		1,000		Ohms

#### Mechanical Specifications

##### Size

Length	1.76 in [44.7 mm]
Width	0.56 in [14.22 mm]
Height	0.56 in [14.22 mm]
Weight	0.05 lbs [22.68 g]

##### Configuration

Connector	TRB 3-Slot Plug
Connector Specification	MIL-STD-1553

#### Material Specifications

Description	Material	Plating
Connector 1 Contact	Bronze	Gold 30 micro inches ASTM-B-488
Gasket	Rubber	
Body	Brass	Nickel ASTM-B-733

#### Environmental Specifications

##### Temperature

Operating Range	-55 to +200 deg C
-----------------	-------------------

**Compliance Certifications** (see [product page](#) for current document)

#### Plotted and Other Data

Notes:

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN PE410-06403-033](#)



## 3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN

### RF Terminations Technical Data Sheet

**PE410-06403-033**

3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99.4% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN PE410-06403-033](https://www.pasternack.com/3-slot-trb-plug-1000-ohm-terminator-no-chain-pe410-06403-033)

URL: <https://www.pasternack.com/3-slot-trb-plug-1000-ohm-terminator-no-chain-pe410-06403-033-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Pasternack does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Pasternack does not assume any liability arising out of the use of any part or documentation.

# PE410-06403-033 CAD Drawing

3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN

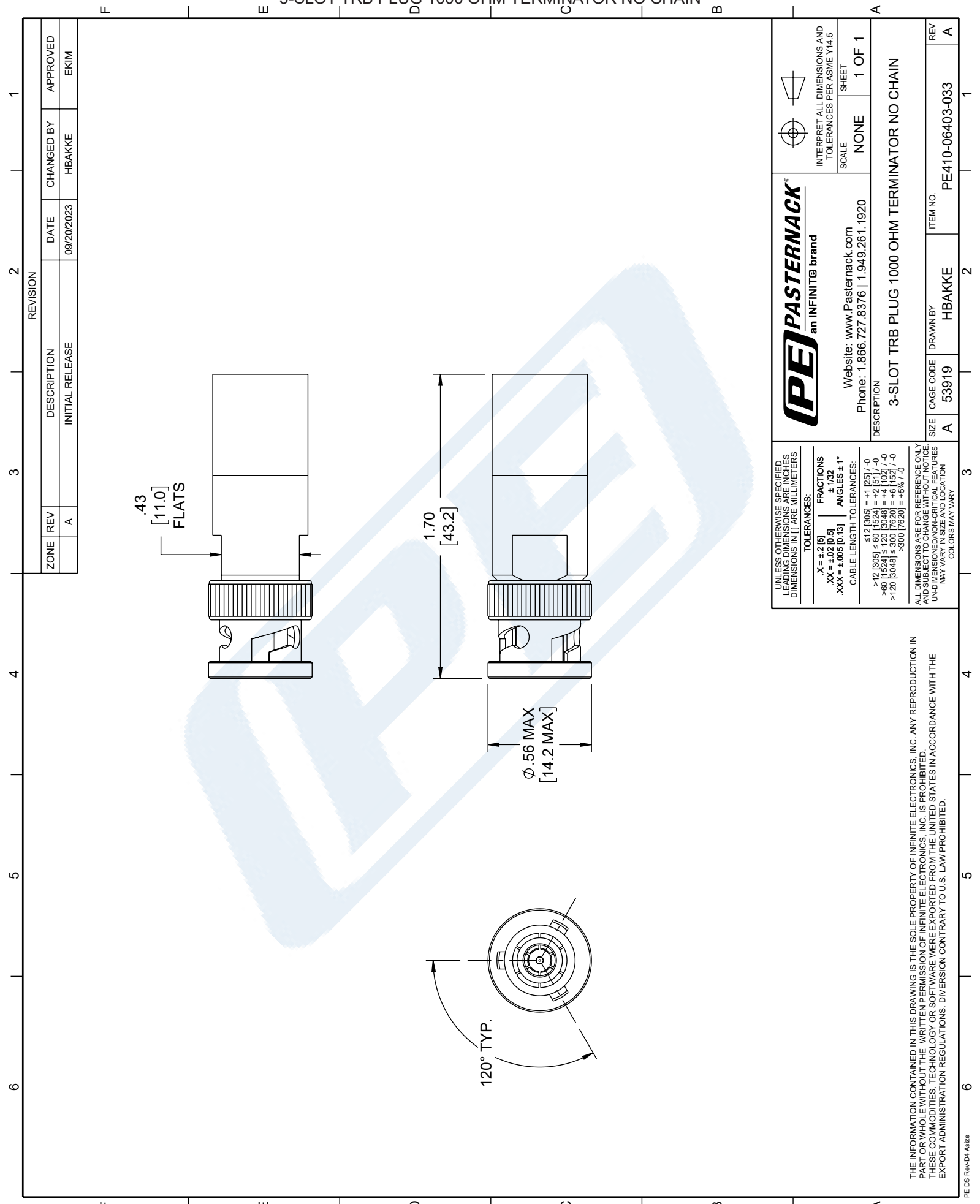

REVISION			
ZONE	REV	DESCRIPTION	DATE
	A	INITIAL RELEASE	09/20/2023
		CHANGED BY	HBAKKE
		APPROVED	EKIM

UNLESS OTHERWISE SPECIFIED LEADING DIMENSIONS ARE IN INCHES DIMENSIONS IN [ ] ARE MILLIMETERS

**TOLERANCES:**

.X = ±2 [5]	FRACTIONS ± 1/32
.XX = ±02 [0.5]	ANGLES ± 1°
.XXX = ±.005 [0.13]	

**CABLE LENGTH TOLERANCES:**

≤12 [305]	±1 [25] / -0
>12 [305] ≤ 60 [1524]	±2 [51] / -0
>60 [1524] ≤ 120 [3048]	±4 [102] / -0
>120 [3048]	±8 [203] / -0

ALL DIMENSIONS ARE FOR REFERENCE ONLY AND SUBJECT TO CHANGE WITHOUT NOTICE UNLESS INDICATED OTHERWISE. CRITICAL FEATURES MAY VARY IN SIZE AND LOCATION. COLORS MAY VARY.

Website: [www.Pasternack.com](http://www.Pasternack.com)  
Phone: 1.866.727.8376 | 1.949.261.1920

INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5

SCALE: NONE

SHEET: 1 OF 1

---

DESCRIPTION: 3-SLOT TRB PLUG 1000 OHM TERMINATOR NO CHAIN

SIZE	CAGE CODE	DRAWN BY	ITEM NO.	REV
A	53919	HBAKKE	PE410-06403-033	A

THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF INFINITE ELECTRONICS, INC. ANY REPRODUCTION IN PART OR WHOLE WITHOUT THE WRITTEN PERMISSION OF INFINITE ELECTRONICS, INC. IS PROHIBITED. THESE COMMODITIES, TECHNOLOGY OR SOFTWARE WERE EXPORTED FROM THE UNITED STATES IN ACCORDANCE WITH THE EXPORT ADMINISTRATION REGULATIONS. DIVERSION CONTRARY TO U.S. LAW PROHIBITED.