



75 Ohm Mini SMB Jack Connector Solder Attachment  
Thru Hole PCB, .200 inch x .055 inch Hole Spacing

RF Connectors Technical Data Sheet

PE4997

**Configuration**

- Mini SMB Jack Connector
- 75 Ohms
- Straight Body Geometry
- Thru Hole Interface Type
- Solder Attachment

**Features**

- Max Frequency 2 GHz
- Gold Plated Brass Contact
- 30 µin minimum contact plating

**Applications**

- General Purpose Test
- Space Saving for PCB Applications

**Description**

Pasternack's PE4997 75 ohm Mini SMB jack connector with solder attachment for thru hole PCB (.200 inch x .055 inch hole spacing) is part of our full line of RF components available for same-day shipping. Our Mini SMB jack connector operates up to a maximum frequency of 2 GHz.

Our 75 ohm Mini SMB jack connector PE4997 datasheet specifications and drawing with dimensions are shown below in this PDF. Pasternack's broad catalog of RF, microwave and millimeter wave connectors allows designers to configure and customize their signal connections however they like. Whether the need is to provide an I/O for a board design, or simply create a custom cable assembly configuration, Pasternack has the right connector for the job. Pasternack can also expertly build your custom cable assemblies for you and ship same-day.

**Electrical Specifications**

Description	Minimum	Typical	Maximum	Units
Frequency Range	DC		2	GHz
Operating Voltage (AC)			335	Vrms

**Mechanical Specifications**

Size	
Length	0.448 in [11.38 mm]
Width/Dia.	0.25 in [6.35 mm]
Height	0.25 in [6.35 mm]
Weight	0.003 lbs [1.36 g]

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [75 Ohm Mini SMB Jack Connector Solder Attachment Thru Hole PCB, .200 inch x .055 inch Hole Spacing PE4997](#)



75 Ohm Mini SMB Jack Connector Solder Attachment  
Thru Hole PCB, .200 inch x .055 inch Hole Spacing

RF Connectors Technical Data Sheet

PE4997

**Material Specifications**

Description	Material	Plating
Contact	Brass	Gold 30 µin minimum
Insulation	PTFE	
Body	Brass	Gold 30 µin minimum

**Environmental Specifications**

**Temperature**

Operating Range -65 to +165 deg C

**Compliance Certifications** (see [product page](#) for current document)

**Plotted and Other Data**

Notes:

75 Ohm Mini SMB Jack Connector Solder Attachment Thru Hole PCB, .200 inch x .055 inch Hole Spacing from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [75 Ohm Mini SMB Jack Connector Solder Attachment Thru Hole PCB, .200 inch x .055 inch Hole Spacing PE4997](#)

URL: <https://www.pasternack.com/mini-smb-jack-standard-thru-hole-pcb-connector-pe4997-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. Pasternack does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and Pasternack does not assume any liability arising out of the use of any part or documentation.

# PE4997 CAD Drawing

75 Ohm Mini SMB Jack Connector Solder Attachment Thru Hole PCB, .200 inch x .055 inch Hole Spacing

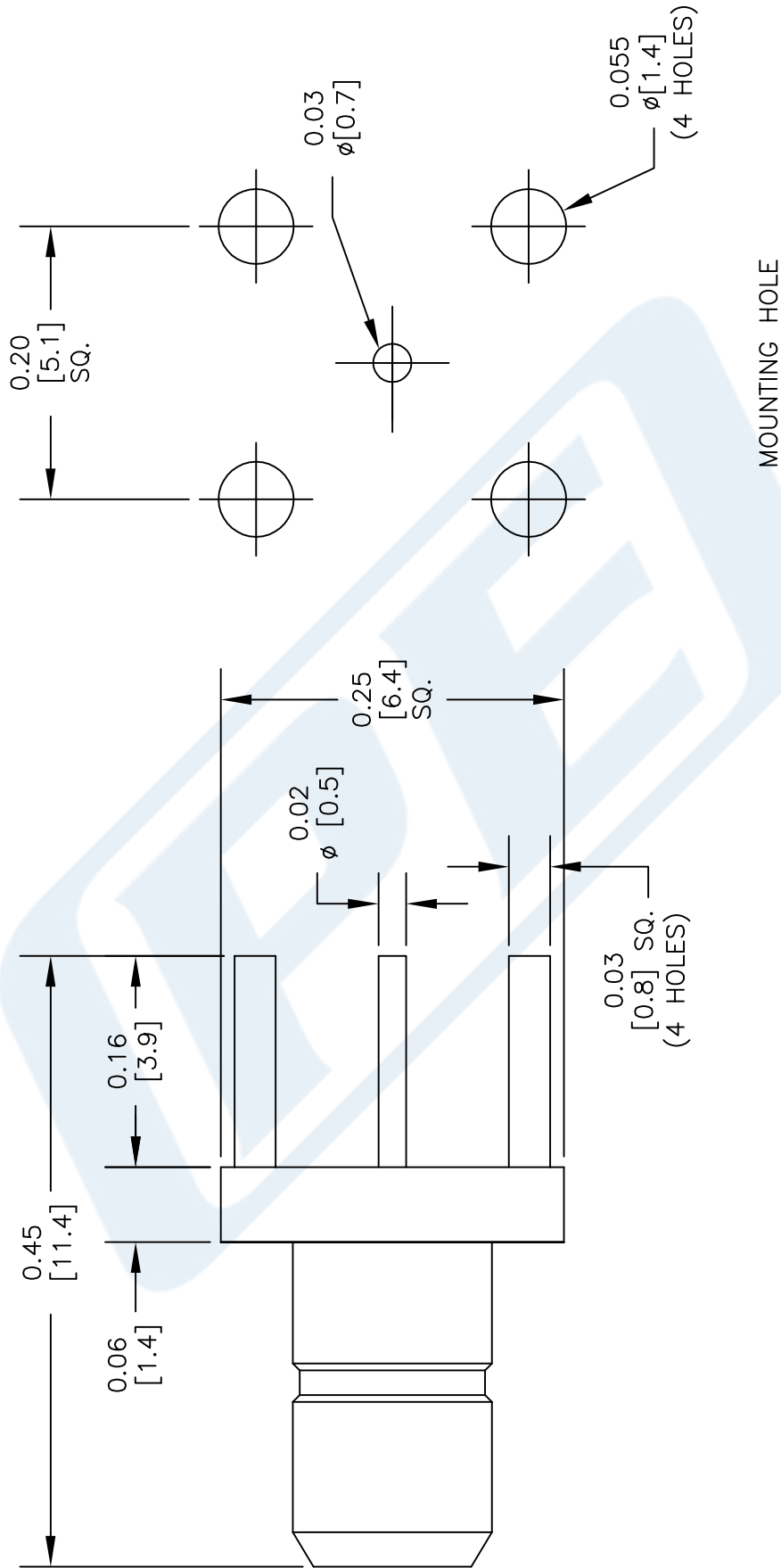

DWG TITLE

**PE4997**

NOTES:  
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.  
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.  
3. DIMENSIONS ARE IN INCHES [mm].

FSCM NO. 53919

CAD FILE 020415

SCALE N/A

SIZE A

150

**PE PASTERNAK®**  
THE ENGINEER'S RF SOURCE

Pasternack Enterprises, Inc.  
P.O. Box 16759 | Irvine | CA | 92623  
Phone: (949) 261-1920 | Fax: (949) 261-7451  
Website: www.pasternack.com | E-Mail: sales@pasternack.com